

decora edge™

Classic Decora®. Faster and Easier to Install.



Leviton's new Decora Edge provides the traditional appearance and superior performance of Decora devices in a new, **easy-to-install** design. The line consists of Single Pole and 3-Way Switches and a NEMA 5-15R 15 Amp duplex Receptacle. Innovative installation features make Decora Edge ideal for larger scope jobs, new home construction and MDU projects as well as retrofit applications.


Installers using Decora Edge will experience an installation process as unique as it is practical. The color-coded levers provide the foundation for quick installation by helping to rapidly identify the correct terminal for wiring, including a lever terminal for the ground wire. The lever system assures a positive connection has been made. This patent pending system has a snap feature with an audible “click” so installers can be confident with every termination.

Applications

Living/Family Rooms, Bedrooms, Kitchens, Bathrooms, Home Offices, Hallways and Basements.

Features and Benefits

- Color-coded lever terminals for fast, efficient wiring; reduces risk of miswiring
- Strap's unique tongue and groove alignment feature offers quicker trim out on multi-gang installations
- Lever doors have snap feature to assure connection has been made; audible click confirms lever door is closed
- No exposed metal parts for enhanced safety; eliminates need for electrical tape
- Lever connectors work with 12 gauge and 14 gauge stranded and solid wire
- Wire openings prevent wire insulation from being inserted into the terminals
- One standard strip gauge for all devices
- Receptacle allows for split circuit usage
- Easily accessible test openings for circuit testers
- Design eliminates the need for fiber washers to hold in mounting screws
- Strap works with any sized wallplate
- Devices coordinate seamlessly with other Decora devices
- Can be used with Decora and Decora Plus™ screwless wallplates

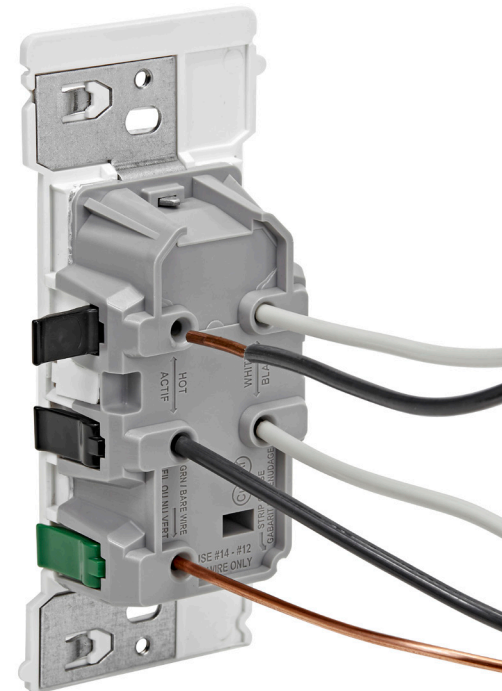

Specifications

E5601, Single Pole Switch

E5603, Three-Way Switch

Amperage: 15 A

Body Material: Thermoplastic

Grounding: Grounding

HP Rating: 1/2HP-120V 2HP-240V-277V

Max. Amperage: 15 Amp

Strap Material: Steel

Termination: Side Lever

Type: Rocker Switch

Voltage: 120/277 VAC

Standards and Certifications:

CSA 22.2 No 111

NOM: NOM Certified

UL 20: File E7458

Warranty: 2-Year Limited

E5325, 15 Amp Duplex Receptacle

Amperage: 15 A

Body Material: Thermoplastic

Blade Type: Straight Blade

Feature: Tamper-Resistant

Grounding: Grounding

NEMA: 5-15R

Termination: Side lever

Type: Duplex Receptacle

Voltage: 125 VAC

Standards & Certifications:


CSA 22.2 No 42: File 152105; Class 6233-01

NOM: NOM Certified

UL 498: File E13399

Warranty: 2-Year Limited

Dimensional Drawings

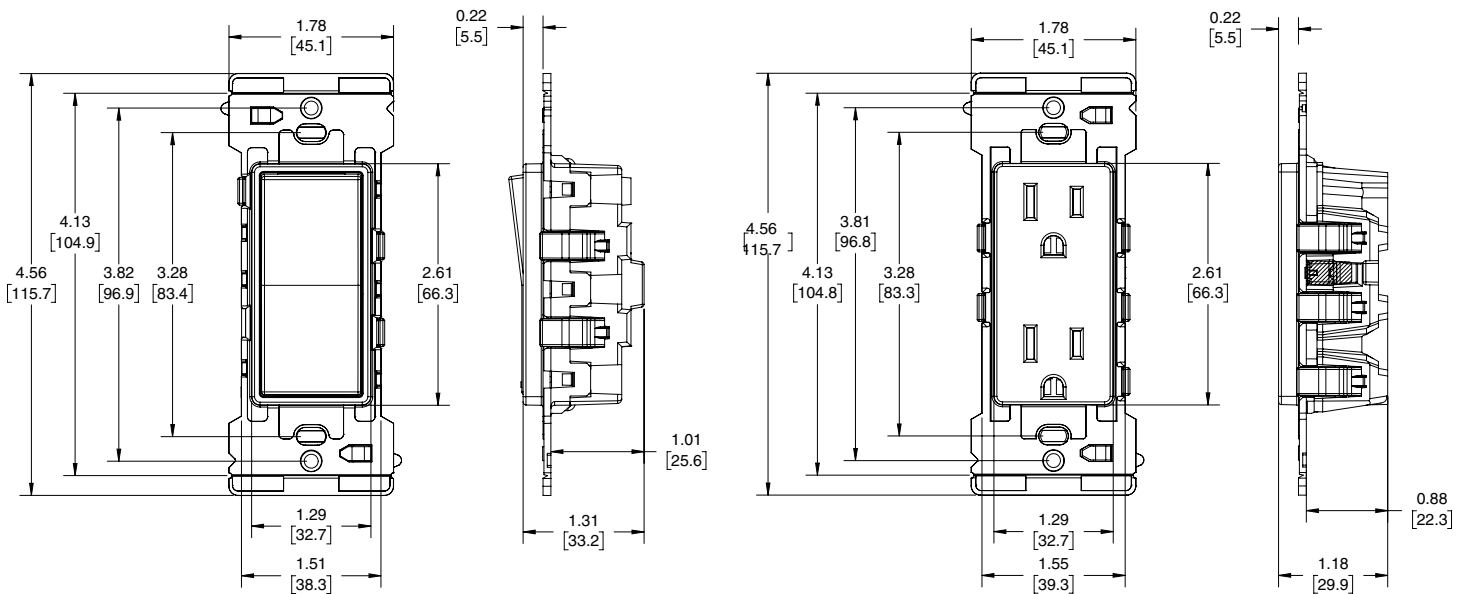

Ordering Information

Cat. No.	Description	Rating	Color
E5601	Single Pole Switch	12 AMP, 120/277V	White
E5603	Three-Way Switch	12 AMP, 120/277V	White
E5325	15 Amp Duplex Receptacle	15 AMP, 125V	White



Leviton Manufacturing Co., Inc.

Tech Line: 1-800-824-3005

Mon-Fri 8am-10pm EST, Saturday 9am-7pm EST, Sunday 9am-5pm EST

For 24/7 product support visit www.leviton.com/support

Visit our Website at: www.leviton.com

© 2023 Leviton Manufacturing Co., Inc. All rights reserved.
All trademarks are the property of their respective owners.

