

Leaded Receptacles, GFCIs & Switches

FAST TERMINATING FOR PIGTAIL WIRING APPLICATIONS

- Eliminates the need to prepare wires for pigtailing
- No screw terminals for faster wiring
- No exposed live metal parts for safer installations

Duplex Receptacles

- Hot, neutral, and ground pre-wired with #12 AWG stranded wire leads, 6" L
- 15 Amp and 20 Amp, 125 Volt
- A grade for every application!

HOSPITAL GRADE Heavy-Duty

Color	15 A	20 A
White	8200-LW	8300-LW
Ivory	8200-LI	8300-LI
Brown	8200-L	8300-L
Gray	8200-LGY	8300-LGY
Black	—	8300-LE
Red	8200-LR	8300-LR


INDUSTRIAL SPECIFICATION GRADE Heavy-Duty

Color	15 A	20 A
White	5262-LW	5362-LW
Ivory	5262-LI	5362-LI
Light Almond	—	5362-LT
Brown	—	5362-L0
Gray	5262-LGY	5362-LGY
Black	5262-LE	5362-LE
Red	5262-LR	5362-LR

COMMERCIAL SPECIFICATION GRADE

Color	STANDARD		DECORA PLUS™	
	15 A	20 A	15 A	20 A
White	5040-W	5340-W*	16252-LW	16352-LW
Ivory	5040-I	5340-I*	16252-LI	16352-LI
Brown	—	5340	16252-L0	—
Gray	—	5340-GY	16252-LGY	16352-LGY
Black	—	—	16252-LE	16352-LE

* NOTE: 50-piece bulk pack available: Ivory 5340-4I and White 5340-4W

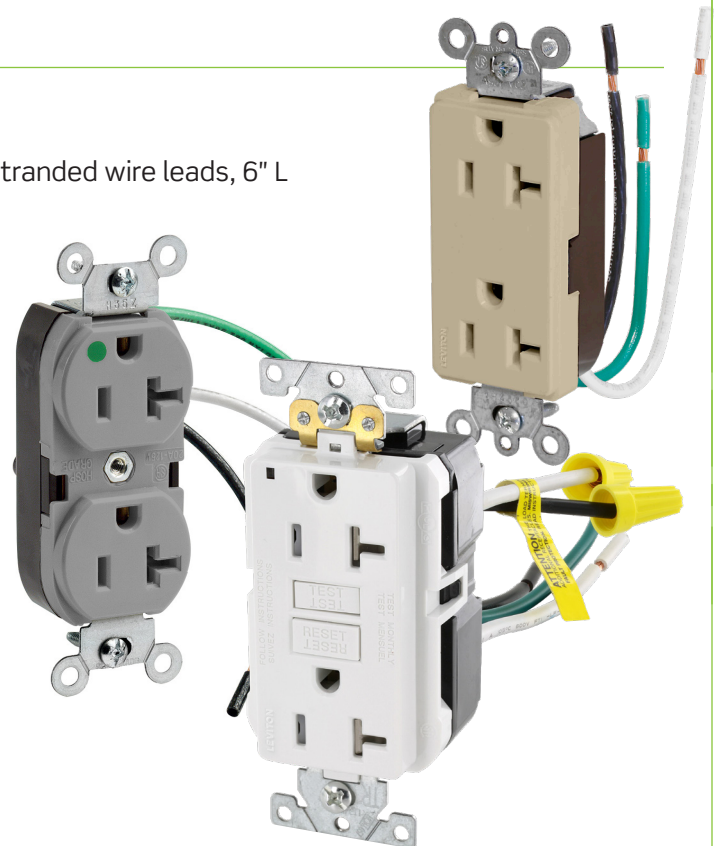

smartlockpro® Tamper-Resistant GFCI

INDUSTRIAL SPECIFICATION GRADE Extra Heavy-Duty

	Color	15 A	20 A
5 PRE-WIRED LEADS	White	GFTR1-5LW	GFTR2-5LW
	Ivory	GFTR1-5LI	GFTR2-5LI
	Light Almond	GFTR1-5LT	GFTR2-5LT
	Brown	GFTR1-5L	GFTR2-5L
	Gray	GFTR1-5LG	GFTR2-5LG
	Black	GFTR1-5LE	GFTR2-5LE
3 PRE-WIRED LEADS (for non-feed-through loads)	Red	GFTR1-5LR	GFTR2-5LR
	White	GFTR1-3LW	GFTR2-3LW
	Ivory	GFTR1-3LI	GFTR2-3LI
	Black	GFTR1-3LE	—

Duplex Receptacles

- Only hot and neutral pre-wired with #12 AWG stranded wire leads, 6" L
- Terminal screw for ground
- 15 Amp and 20 Amp, 125 Volt



HOSPITAL GRADE

Heavy-Duty

Color	15 A	20 A
White	8200-CW	8300-CW
Ivory	8200-CI	8300-CI
Gray	8200-CGY	8300-CGY

INDUSTRIAL SPECIFICATION GRADE

Heavy-Duty

Color	15 A	20 A
Ivory	5262-CI	5362-CI
Gray	5262-CGY	—

COMMERCIAL SPECIFICATION GRADE

Color	STANDARD		DECORA PLUS™	
	15 A	20 A	15 A	20 A
White	5040-CW	5340-CW	—	16352-CW
Ivory	5040-CI	5340-CI	—	16352-CI
Gray	5040-CGY	5340-CGY	—	16352-CGY


Toggle Switches

- Pre-wired with #12 AWG stranded wire leads, 6" L
- 15 Amp and 20 Amp, 120/277 Volt
- Single-Pole and 3-Way

INDUSTRIAL SPECIFICATION GRADE

Extra Heavy-Duty

Color	SINGLE-POLE		3-WAY	
	15 A	20 A	15 A	20 A
White	1241-W	1243-W	—	1244-W
Ivory	1241-I	1243-I	1242-I	1244-I
Gray	—	1243-LGY	—	1244-LGY

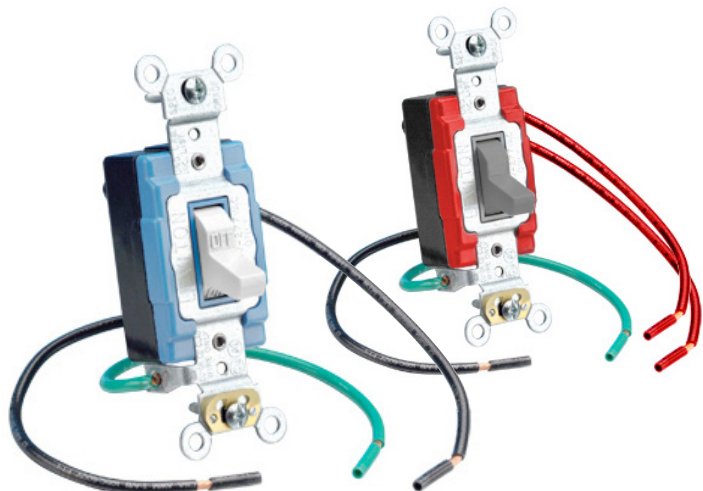

Visit our Website at:

leviton.com/receptaclegrades

email: commercial@leviton.com

Q-1133A

040124

Leviton Manufacturing Co., Inc.

201 N Service Rd, Melville, NY 11747

Telephone: 1-800-323-8920 • FAX: 1-800-832-9538

Tech Line: 1-800-824-3005 (M-F 8AM-10PM; Sat 9AM-7PM; Sun 9AM-5PM)

© 2024 Leviton Manufacturing Co., Inc. All rights reserved.