

Q2 2026



New Products Supplement

The latest solutions within electrical distribution



THE FUTURE IS ON®

New Products

NEW GreenConnect™ — Wireless Done Right!

GreenConnect™ makes wireless lighting control easy with a simple, scalable solution. With Push-to-Pair technology, GreenConnect™ does not require a room controller, hub, or app. Fully programmable by the contractor, setup is quick and effortless without any factory commissioning required. Add wireless control to virtually any switching or dimming device without new wiring, an ideal solution for retrofits and new construction.



NEW Lever Edge™ — The Future of Wiring

Leviton's Lever Edge™ wiring devices provide the classic appearance and superior performance of Leviton devices in a new, faster and easier to install design. This newly UL-approved wiring method features spring action clamping levers proven to install up to 3.5X faster than traditional wiring devices. The color-coded levers close with an audible click to help reduce mistakes and terminate with confidence. No exposed metal parts, including the industry first rapid screwless grounding, means you can terminate without tools, torque adjustments, or tape. Lever Edge™ devices are ideal for new home construction, retrofits, MDU projects, commercial sites, and industrial applications. See how much time and money you can save with Lever Edge™.

Lever Edge™ Residential Switches, Dimmers, Receptacles, and GFCIs

- Accepts multiple copper wire sizes and types with reusable terminations
- Larger straps help hide imperfections, work with multiple sizes wallplates, and have a tongue and groove alignment system for multi-gang installations

Lever Edge™ Commercial Receptacles

- A single wraparound galvanized steel strap on commercial grade receptacles
- Ribbed levers for easy, secure grip

Lever Edge™ Black & White® Industrial Plugs and Connectors

- Durable nylon housing with HB or better flammability ratings
- Wider ribs on housing strengthens grip while installing
- Clear back cover to easily view connection status



NEW Smooth Slim Downlight with Selectable Lumen Output & CCT

The DFR Series is a direct mount downlighting solution that is ultra slim, making it the ideal choice for both new construction and remodeling installations in low ceilings. Available in 4- and 6- inch round apertures that are IC rated and suitable for both indoor and outdoor covered ceiling applications. Smooth beam distribution and superior color quality for even illumination.

Direct mount downlighting solution; no existing housing or junction box required

- Available in 4- and 6-inch diameter models
- 1/2-Inch profile for low fixture depth
- Black trim ring available
- Field selectable lumen output
- Field selectable color temperature (CCT) — Select from 2700K, 3000K, 3500K, 4000K, and 5000K



NEW LED Advanced Dimmers No-Neutral Required

LED Advanced dimmers use dimming technology previously only available in higher end lighting controls, combining affordability with high quality dimming of modern LED lighting



NEW VerifEye® Series 2500

The VerifEye® Series 2500 Submeter delivers a scalable, code-compliant energy monitoring solution designed for pulse output and Modbus RTU based power consumption. Housed in a NEMA 3R enclosure, the Series 2500 is suitable for both indoor and outdoor environments, offering flexible mounting options and tamper-resistant features.

- **One SKU simplicity:** Single model supports single-, two-, and three-phase applications
- **Fast, easy installation:** Tool-free wiring using WAGO®* connectors
- **Programming wizard:** Built-in configuration wizard guides installers
- **Built-In diagnostic icons:** Help verify proper wiring and configuration

*WAGO is a registered trademark of WAGO GMBH & CO. KG.



NEW Surge Protective Panels

Leviton's latest surge protective devices include both Type 1 and Type 2 panels for residential, commercial, and industrial applications. These new panels feature improved surge performance ratings, improved enclosure ratings, and are compliant with the latest 2023 NEC and UL 1449 5th edition requirements.

The R, P, B, M, and X Series panels feature NEMA 4 or 4X outdoor ratings and offer a range of solutions from compact and easily installed panels tailored for residential use, to cutting-edge panels featuring LCD screens and advanced functionalities such as surge counting and performance monitoring for industrial use.

Flush Mount Flanges

Available for all Leviton Surge Protective Panels in either Polycarbonate or Aluminum.



NEW High Performance 50 Amp Heavy Duty EV Flush and Surface Mount Receptacles

The perfect option for homeowners who prefer a plug-in EV charging application to a hardwired application, and for future-focused new construction MDU projects that want to present an EV-ready environment.

- Robust design can sustain the necessary extended charge time and high frequency insertions EV chargers require
- Features heavy-gauge, high -performance copper contacts and durable, high-impact nylon
- Pressure-wire terminal connections ensures full-contact with the conductors

Weather-Resistant Cover

- Available all-in-one pre-assembled outlet and cover code compliant solution with pre-wired ground
- Specifically designed for outdoor, weather resistant EV charging with multiple knockout options for flexible installation
- Available weatherproof clear cover flush mount code compliant solution



NEW ArcArrest® Switch-Rated Pin and Sleeve Devices

ArcArrest® Switch-Rated Pin & Sleeve devices provide a local means of disconnect as required by NEC and are rated for both branch and motor circuit disconnects.

By combining a wall-mounted disconnect with a plug and connector, they deliver greater flexibility and portability. Even under load, there's no exposure to live components or arc flash. Built with watertight ratings, they're engineered to perform reliably in harsh industrial environments.



NEW USB In-Wall Receptacles


Declutter your space with charging power where you need it. Two charging ports deliver a combined total of 18 watts of power. Built-in smart chip recognizes the individual device's charging requirements to optimize the charge Type A/A replacement is ideal for high-volume, price-sensitive projects.

Plus, three upgrade tiers including Power Delivery and Ultra-Fast 60W options perfect for high end upgrades to custom homes.



NEW EV Series PRO Smart Commercial and Fleet Charging Solutions

- Multi-site, multi-station management in a single dashboard
- Real-time analytics and data
- Create multiple user groups for access control
- In-app and RFID access, including RFID access with existing badges, room keys, etc.
- Fleet telematics integration capabilities
- Now available in dual port

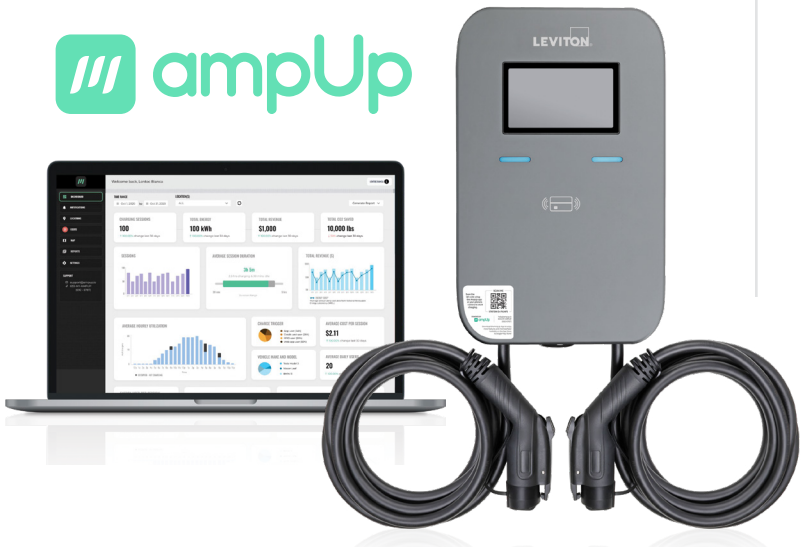

NEW Floor Boxes

From wood frame construction to concrete pours, our floor boxes offer a full portfolio of products to satisfy the needs of commercial applications. Accommodating data, AV and power connectivity where it's needed most, we provide an all encompassing solution down to the devices inside the box. Our floor box systems are easy to install and built to last, making them a superior choice for commercial settings. Type A/C USB Floor Boxes are also available.



NEW EV Series Smart Home Plug-In

Introducing Leviton's first Plug-In EV Series Charging Station! The new 40 Amp EV Series Smart Home features a 25' charging cable and a NEMA 14-50 plug, compatible with Leviton's new Industrial Grade EV Charging Receptacles. Additionally, the stations are compatible with the My Leviton App, allowing for control of the entire home, from load center to lighting to EV charger.



Featured Products

Leviton Load Center

Access whole-home energy use data from anywhere with the award-winning Leviton Load Center and My Leviton app. New 2nd Gen Smart Circuit Breakers provide unparalleled control of your home's electrical system, including remote breaker scheduling and control to save energy, and intuitive insights into energy usage from the grid and alternate energy sources.

- Modern design with intuitive functionality and appealing aesthetics
- LEDs communicate trip condition and type of fault (AF/GF)
- Modular design allows for easy upgrades to smart circuit breakers
- Remote ON/OFF control and time/day-based circuit scheduling
- Receive notifications and alerts for breaker activity, anomaly detection and energy usage
- Whole home energy monitoring
- Allows for all wiring at rough-in, without any circuit breakers present
- Only Fully Plug-On Breaker System (up to 60A)
- Leviton Circuit Breakers simply snap in for up to 25% faster install



Decora Smart®

It's easy to create a smart home by adding smart switches, dimmer switches, smart plugs, outlets, motion sensors and fan controllers that will help make your life safer and more convenient. Schedule and control using the My Leviton app or use your voice with Amazon Alexa™, Google Assistant™, or HomeKit™/Siri®.

You can also connect locally to any Matter enabled smart home platform of your choice securely and reliably with a simple firmware update available in the My Leviton app. Decora Smart® offers smart solutions for every room and home, new or old, including homes that may not have neutral wiring.

Leviton's latest Decora Smart dimmer and switch deliver high-performing dimming and control, a slimmer profile for easier installation, and My Leviton features like scheduling, scenes, and convenience.



HF GFCI Receptacles

SmartlockPro® High-Frequency Interoperability Devices

Leviton has updated our technology to combat the interoperability issues from appliances operating at high frequencies while driving standard updates to ensure this compatibility. Our existing SmartlockPro® devices* found on shelves today meet the latest UL standards for HF interoperability, ensuring consistent performance across a wide range of modern electrical systems and appliances.

In addition to being High-Frequency ready, our GFCI line features:

- Auto self-test ground-fault protection
 - Reset Lockout Technology prevents unsafe resets
 - LED Status indicator light for quick feedback
 - Slimmest in-box depth for easy installs
- *Excluding AFCI combo, Nightlight, USB Combo, and Combo Switch devices (coming soon)



Commercial and Residential Sensors

Leviton offers a wide selection of occupancy and vacancy sensors for commercial and residential applications. From wall and ceiling mounted to wall switch and wireless, with passive infrared, humidity, ultrasonic or multi-technology sensing; Leviton sensors provide smart energy saving solutions for indoor and outdoor use for commercial and residential applications.



Smart Ceiling Mount Sensors (CMS)


Smart Ceiling Mount Sensors (CMS) deliver an all-in-one code compliant solution. The line simplifies advanced lighting controls by integrating several control strategies into a self-contained, cost-effective, and easy-to-install device. Fully configurable with the Smart Sensor App.

CMS meets IECC, ASHRAE 90.1, and California Title 24 requirements with occupancy/vacancy sensing, 0–10V dimming, partial-ON, partial-OFF, daylighting, receptacle control, and demand response. CMS is also UL924 Listed for emergency lighting. It wirelessly links up to five devices to cover 10,000 sq ft and control up to ten zones, with flexible setup options, multi-way, scheduling, and quick multi-room replication.



Smart Wallbox Sensors

Smart Wallbox Sensors combine occupancy/vacancy sensing with ON/OFF switching, line voltage or low voltage (24VDC) 0-10V dimming, or 1000W dimming to provide a simple commercial grade solution for easy energy savings, local control, and code compliance. Smart Wallbox Sensors offer easy programming and configuration with the Smart Sensor App, an out-of-the-box default mode for auto-ON/auto-OFF operation with a 10-minute timeout, and convenient pushbutton programming for common room settings. Ideal for commercial spaces up to 1,100 SF.

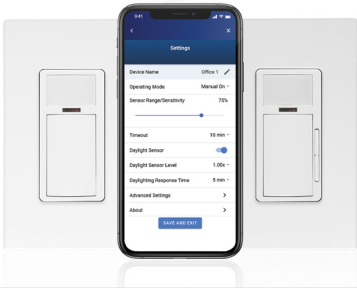

VerifEye® Submetering Solutions

VerifEye® delivers a complete utility submetering solution. The line includes a comprehensive line of leading-edge submeters, communication products, and software solutions to help commercial, residential, and industrial facilities manage costs and conserve energy. The cost-effective scalability and integration provide timely solutions that can be expanded for future needs. Submetering expertise, service and support from start to finish from a name you can trust.



Marine Power

Announcing the new, full portfolio of Leviton power pedestals now including metallic pedestals, bringing power to previously unreachable locations. Designed for docks, marinas, boatyards, and waterfront facilities, our portfolio includes power pedestals, ladders, fenders, cleats, piling caps, accessories, marine grade pin & sleeve devices, Wetguard watertight devices, and other durable solutions for dockside power. Applications include marinas, commercial spaces, RV parks and campsites.

Metallic Pedestals

- Designed to resist saltwater, UV exposure, and extreme outdoor conditions for dependable performance year-round
- Provides reliable electrical connections through safe, high quality power distribution

Non-Metallic Pedestals

- Daylight sensing LED lighting
- Easy wiring and maintenance access



Med Strips

Leviton's load monitoring med-strip with Inform™ technology is the only solution on the market addressing NFPA 99 load monitoring requirements in the patient care vicinity.

Inform® Technology

Inform™ is a technology platform that enables Leviton products to provide real-time product data to the end-user. This data is used to improve safety, efficiency, and productivity. The feature set varies by product and can include line of sight local monitoring and remote monitoring. Remote monitoring data is sent to the Inform™ app via Wi-Fi®.



GreenConnect™

GreenConnect Wireless	
Description	Cat. No.
GreenConnect Wireless 20A ON/OFF Switching Load Controller	ZKS00-DOW
GreenConnect Wireless 10A 0-10V Dimming Load Controller	ZK700-DOW
GreenConnect Wireless 800W Phase Cut Dimming Load Controller	ZKM00-10W
GreenConnect Wireless ON/OFF Wall Switch	ZBS00-D0Z
GreenConnect Wireless 0-10V Wall Dimmer, 120-277VAC	ZB700-D0Z
GreenConnect Wireless 0-10V Wall Dimmer, 347VAC	ZB700-30Z
GreenConnect Wireless 1000W Forward Phase Wall Dimmer	ZBM00-10W
GreenConnect Battery-Powered Companion Switch	ZBK00-CSW
GreenConnect Battery-Powered Companion Dimmer	ZBK00-CDW
GreenConnect Wireless PIR Occupancy Sensor and Photocell, 1,500SF	ZC015-BIW
GreenConnect Wireless 20A Controlled Receptacle	ZBR20-1SW

Lever Edge™

Residential Grade Devices			
Description	Color	Rating	Cat. No.
Single Pole Switch	White	15A 120/277V	E5601-W
3-Way Switch			E5603-W
Tamper-Resistant Duplex Receptacle		15A, 125V	E5325-W
Tamper Resistant Duplex Receptacle		20A, 125V	E5825-W
3-Way Rocker Slide Dimmer Switch		120V	ESL01-1LW
Tamper Resistant GFCI		15A, 125V	EGFT1-W
Weather/Tamper Resistant GFCI		15A, 125V	EGFW1-KW

Commercial Grade Devices			
Description	Color	Rating	Cat. No.
Duplex Receptacle	White	20A, 125V	E5362-SW
Tamper-Resistant Duplex Receptacle		20A, 125V	ET563-W

Black & White Devices		
Description	NEMA Configuration	Cat. No.
Plug	NEMA 5-15P	5266E
	NEMA 5-20P	5366E
	NEMA L5-20P	2311E
	NEMA 6-20P	5466E
	NEMA L6-20P	2321E
	NEMA L6-30P	2621E
	NEMA L7-15P	4770E
	NEMA L14-20P	2411E
	NEMA L14-30P	2711E
Connector	NEMA 5-15R	5269E
	NEMA 5-20R	5369E

LED Downlights with Selectable CCT

Baffle Slim Led Downlight With Selectable CCT	
Description	Cat. No.
4" Round Baffle Slim LED Downlight	DBR40-S1W
6" Round Baffle Slim LED Downlight	DBR60-S1W
8" Round Baffle Slim LED Downlight	DBR80-S1W
4" Square Baffle Slim LED Downlight	DBS40-S1W
6" Square Baffle Slim LED Downlight	DBS60-S1W
4" round aperture Adjustable Slim Downlight	DAR40-S1W
6" round aperture Adjustable Slim Downlight	DAR60-S1W
Universal Fit New Construction Mounting Plate for 4-, 6- and 8-Inch Round DBR Series Downlights	DBRUX-H00
Universal Fit New Construction Mounting Plate for 4-, 6- Inch Square Slim Series Downlights	DBSUX-H00
4-inch Round Aperture Smooth Slim Downlight with Selectable Lumen Output and CCT	DFR40-S1W
6-inch Round Aperture Smooth Slim Downlight with Selectable Lumen Output and CCT	DFR60-S1W

Fire-Rated Baffle Slim Downlight With Selectable CCT	
Description	Cat. No.
4" Round Aperture Fire-Rated Baffle Slim Downlight	FBR40-S1W
6" Round Aperture Fire-Rated Baffle Slim Downlight	FBR60-S1W
Universal Fit New Construction Mounting Plate for 4- and 6- Inch Round Slim Series Downlights	DBRCX-H00
20 Foot Extension Cord Cable for 4- and 6- Inch Fire-Rated Baffle Slim Series Downlights	FB00X-ETW

SDR Series Surface Mount Downlights and Accessories	
Description	Cat. No.
5" Round Aperture Surface Mount Downlight	SDR50-S1W
7" Round Aperture Surface Mount Downlight	SDR70-S1W
9" Round Aperture Surface Mount Downlight	SDR90-S1W
5" Matte Black Trim Ring for Surface Mount Downlights	SDR5X-T0E
7" Matte Black Trim Ring for Surface Mount Downlights	SDR7X-T0E
9" Matte Black Trim Ring for Surface Mount Downlights	SDR9X-T0E

LED Advanced Dimmers No-Neutral Required

Please visit [leviton.com/products/residential/dimmers](https://www.leviton.com/products/residential/dimmers) for complete ordering information, or contact your Leviton representative.

VerifEye® Series 2500

Please visit [leviton.com/verifeye](https://www.leviton.com/verifeye) for complete ordering information, or contact your Leviton representative.

Surge Protective Panels

Type 1					
R & P Series Surge Protective Panels					
Series	Voltage	Phase	Maximum Continuous Operating Voltage (MCOV)	Voltage Protection Rating (VPR) Performance Data	Cat. No.
R	120/240 VAC/CA	Split Phase	180V/360V*	L-N: 700V, L-L: 1200V	R2120-B
P	120/240 VAC/CA	Split Phase	180V/360V*	L-N: 700V, L-G: 1200V, N-G: 600V, L-L: 1200V	P2120-B
	208Y/120 VAC/CA	Three Phase WYE	150V/300V*	L-N: 600V, L-G: 600V, N-G: 600V, L-L: 1000V	P3120-YB
	480Y/277 VAC/CA		350V/700V*	L-N: 1200V, L-G: 2500V, N-G: 1000V, L-L: 2000V	P3277-YB
Accessories for Flush Mount Applications					
Series	Voltage				Cat. No.
R	R Series Flush Mount Flange - Polycarbonate				RSURG-FLG
P	P Series Flush Mount Flange - Polycarbonate				PSURG-FLG

Type 2					
B, M & X Series Surge Protective Panels					
Series	Voltage	Phase	Maximum Continuous Operating Voltage (MCOV)	Voltage Protection Rating (VPR) Performance Data	Cat. No.
B	120 VAC/CA	Single Phase	180V	L-N: 700V, L-G: 700V, N-G: 700V	B1120-B
	120/240 VAC/CA	Split Phase	180V/360V*	L-N: 700V, L-G: 700V, N-G: 700V, L-L: 1200V	B2120-B
	208Y/120 VAC/CA	Three Phase WYE	150V/300V*	L-N: 700V, L-G: 700V, N-G: 600V, L-L: 1200V	B3120-YB
	240 VAC/CA		275V	L-G: 1000V, L-L: 1200V	B3240-DB
	120/240 VAC/CA	Hi-Leg Delta	180/275V*	L-N: 800V, L-G: 700V, N-G: 700V, L-L: 1500V	B3240-HB
	480Y/277 VAC/CA	Three Phase WYE	350V/700V*	L-N: 1200V, L-G: 1200V, N-G: 1200V, L-L: 2500V	B3277-YB
	347/600 VAC/CA		440V/880V*	L-N: 1500V, L-G: 1500V, N-G: 1500V, L-L: 3000V	B3347-YB
	480 VAC/CA	Three Phase Delta	550V	L-G: 1800V, L-L: 1800V	B3480-DB
M	120/240 VAC/CA	Split Phase	180V/360V*	L-N: 700V, L-G: 800V, N-G: 600V, L-L: 1200V	M2120-B
	208Y/120 VAC/CA	Three Phase WYE	150V/300V*	L-N: 600V, L-G: 700V, N-G: 600V, L-L: 1000V	M3120-YB
	240 VAC/CA	Three Phase Delta	275V	L-G: 900V, L-L: 1800V	M3240-DB
	480Y/277 VAC/CA	Three Phase WYE	350V	L-N: 1200V, L-G: 1200V, N-G: 1000V, L-L: 2000V	M3277-YB
	347/600 VAC/CA		440V/880V*	L-N: 1500V, L-G: 1500V, N-G: 1500V, L-L: 2500V	M3347-YB
	480 VAC/CA	Three Phase Delta	550V	L-G: 1800V, L-L: 1800V	M3480-DB
X	600 VAC/CA		680V	L-G: 2000V, L-L: 2000V	M3600-DB
	120/240 VAC/CA	Split Phase	175V/300V*	L-N: 600V, L-G: 700V, N-G: 600V, L-L: 900V	X2120-C
	208Y/120 VAC/CA	Three Phase WYE	150V/300V*	L-N: 600V, L-G: 600V, N-G: 600V, L-L: 1000V	X3120-YC
	480Y277 VAC/CA		320V/700V*	L-N: 1200V, L-G: 1200V, N-G: 1200V, L-L: 2000V	X3277-YC

Accessories for Flush Mount Applications		
Series	Voltage	Cat. No.
B	B Series Flush Mount Flange - Aluminum	BSURG-FLG
M	M Series Flush Mount Flange - Aluminum	MSURG-FLG
X	X Series Flush Mount Flange - Aluminum	XSURG-FLG

*Second voltage refers to L-L rating.

High Performance 50 Amp Heavy Duty Flush Mount Receptacles

EVSE Growth Products	
Description	Cat. No.
50 Amp EV Charging Receptacle/Outlet, Heavy Duty	1450R
50 Amp EV Charging Receptacle/Outlet, Heavy Duty, Weather-Resistant	1450W
50A EV Charging Outlet with Outdoor Weather-Proof Cover, Surface Mount	EVCVM-50
50A EV Charging Outlet with Outdoor Weather-Proof Cover, Flush Mount	EVCVP-50

ArcArrest® Switch-Rated Pin & Sleeve

Please visit [leviton.com/arcarrest](https://www.leviton.com/arcarrest) for complete ordering information, or contact your Leviton representative.

USB Charger Receptacles

Residential USB In-Wall Chargers	
Description	Cat. No.
Decora® 18W USB Type A/Type C In-Wall Charger with 15A Tamper Resistant Outlet, 125V	BAC15
Decora® 18W USB Type A/Type C In-Wall Charger with 20A Tamper Resistant Outlet, 125V	BAC20
Decora® 30W USB Dual Type C In-Wall Charger with 15A Tamper Resistant Outlet, 125V	CC1X3
Decora® 30W USB Dual Type C In-Wall Charger with 20A Tamper Resistant Outlet, 125V	CC2X3
Decora® USB Charger Combination Device, Type A and Type-C USB In-Wall Charger with Duplex Tamper-Resistant , 15A-125V	AC1X3
Decora® USB Charger Combination Device, Type A and Type-C USB In-Wall Charger with Duplex Tamper-Resistant , 20A-125V	AC2X3
Decora® 30W Power Delivery USB Dual Type C In-Wall Charger with 15A Tamper Resistant Outlet, 125V	CC1P3
Decora® 30W Power Delivery USB Dual Type C In-Wall Charger with 20A Tamper Resistant Outlet, 125V	CC2P3
Decora® 60W USB Power Delivery Type A/Type C In-Wall Charger with 15A Tamper Resistant Outlet, 125V	AC1P6
Decora® 60W USB Power Delivery Type A/Type C In-Wall Charger with 20A Tamper Resistant Outlet, 125V	AC2P6
Decora® 60W USB Power Delivery Dual Type C In-Wall Charger with 15A Tamper Resistant Outlet, 125V	CC1P6
Decora® 60W USB Power Delivery Dual Type C In-Wall Charger with 20A Tamper Resistant Outlet, 125V	CC2P6
Decora® 25W USB Type A/Type C In-Wall Charger with 15A Weather Resistant Outlet, 125V	W5633
Decora® 25W USB Type A/Type C In-Wall Charger with 20A Weather Resistant Outlet, 125V	W5833
Decora® Combination Device, 24W USB Type A/Type C In-Wall Charger, SmartlockPro® Self-Test GFCI, with 15A Tamper Resistant Outlet, 125V	GUAC1
Decora® Combination Device, 24W USB Type A/Type C In-Wall Charger, SmartlockPro® Self-Test GFCI, with 20A Tamper Resistant Outlet, 125V	GUAC2

Floor Boxes

Please visit [leviton.com/products/commercial/floor-boxes](https://www.leviton.com/products/commercial/floor-boxes) for complete ordering information, or contact your Leviton representative.

EV Series Pro Smart Commercial and Fleet Charging

EV Series Smart Home Plug-In	
Description	Cat. No.
EV Series Pro Level 2 Electric Vehicle Charging Station, 48A	EV48G
EV Series Pro Level 2 Electric Vehicle Charging Station, 80A	EV80S

EV Series Smart Home Plug-In

EV Series Smart Home Plug-In	
Description	Cat. No.
EV Series Smart Home Level 2 Charging Station, 40 Amp (9.6kW) Plug-In	EV40P

Load Center

Please visit [leviton.com/loadcenter](https://www.leviton.com/loadcenter) for complete ordering information, or contact your Leviton representative.

Decora Smart® Wi-Fi® 2nd Gen Devices

Decora Smart® with Wi-Fi® 2nd Gen Technology	
Description	Cat. No.
Scene Controller Switch (2nd Gen)	D2SCS--1BW
4-Speed Fan Controller (2nd Gen)	D24SF-1BW
600W Dimmer (2nd Gen)	D36HD-1BW
15A Switch (2nd Gen)	D315S-1BW
Mini Plug-In Dimmer (2nd Gen)	D23LP-1BW
Mini Plug-In Switch (2nd Gen)	D215P-1BW
15A Tamper-Resistant Outlet (2nd Gen)	D215R-1BW
Motion Sensing Dimmer (2nd Gen)	D2MSD-1BW
ELV/LED Phase-Selectable Dimmer	D2ELV-1BW
0-10V Dimmer	D2710-1BW

Decora® Smart Plug, Outdoor, Wi-Fi

Decora Smart® with Wi-Fi Single Pole, 3-Way/Multi-Location — Neutral Wire Required			
Description		Color	Cat. No.
Outdoor Plug-in Switch	15A Gen Use 5A LED/CFL/Electronic Ballast 1500W Inc/Halogen 12A Magnetic Ballast/MLV 3/4 HP Motor	White	D2150-1R

Decora Smart® No-Neutral Devices

Decora Smart® No-Neutral Dimmer, Switch, and Wi-Fi Bridge		
Description	Color	Cat. No.
Plug-In Wi-Fi Bridge (Required for use with DN6HD and DN15S)	White	MLWSB-1BW
600W No-Neutral Dimmer		DN6HD-1BW
15A No-Neutral Switch		DN15S-1BW

Decora Smart® Companion Devices

Decora Smart® Companion Devices for 3-Way or More Applications	
Description	Cat. No.
Wire-Free Anywhere Dimmer Companion	DAWDC-1BW
Wire-Free Anywhere Switch Companion	DAWSC-1BW
Wired Dimmer Companion	DD00R-DLZ
Wired Switch Companion	DD0SR-DLZ

Commercial Sensors

Smart Wallbox Sensors		
Description	Cat. No.	Color*
Smart PIR 0-10V Dimming Wallbox Sensor	ODD10-ID	W, I
Smart PIR Wallbox Sensor	ODS15-GD	W*
Smart PIR Wall Switch Sensor	ODS15-ID	W, I*
Smart PIR Wall Switch Sensor	ODS15-Il	W, I*
Smart PIR 24V Dimming Wallbox Sensor	ODD24-ID	W*
Smart PIR 1000W Dimming Sensor	ODP10-Il**	W, I
Smart Multi-Tech Wallbox Sensor, White	ODSMT-MDW	
Smart Multi-Tech Wallbox Sensor, Ivory	ODSMT-MDI	
Smart Multi-Tech 0-10V Dimming Wallbox Sensor, White	ODDMT-MDW	
Smart Multi-Tech 0-10V Dimming Wallbox Sensor, Ivory	ODDMT-MDI	
Smart Multi-Tech 24V Dimming Wallbox Sensor, White	ODDMT-MLW	
Smart Multi-Tech 1000W Dimming Wallbox Sensor, White	ODP10-M1W	
Smart Multi-Tech 1000W Dimming Wallbox Sensor, Ivory	ODP10-M1I	

*Color Change Faceplates available for Black, Red, Gray, Light Almond and White.

Smart Ceiling Mount Sensors (CMS)	
Description	Cat. No.
Smart PIR Ceiling Mount Sensor, 0-10V Dimming, 2-zone, 450-1,500SF, 120-277VAC	ACY15-DIW
Smart Multi-Tech Ceiling Mount Sensor 0-10V Dimming, 1-zone, 500SF, 120-277VAC	AC705-DMW
Smart Multi-Tech Ceiling Mount Sensor, 0-10V Dimming, 2-zone, 2,000SF, 120-277VAC	ACY20-DMW
Smart PIR Ceiling Mount Sensor, Switching, 1-zone, 450-1,500SF, 120-277VAC	ACS15-DIW
Smart Multi-Tech Ceiling Mount Sensor, Switching, 1-zone, 500SF, 120-277VAC	ACS05-DMW
Smart Multi-Tech Ceiling Mount Sensor, Switching, 1-zone, 1,000SF , 120-277VAC	ACS10-DMW
Smart Multi-Tech Ceiling Mount Sensor, Switching, 1-zone, 2,000SF , 120-277VAC	ACS20-DMW
Smart Multi-Tech Ceiling Mount Sensor, Switching, 2-zone, 500SF, 120-277VAC	AC205-DMW
Smart Multi-Tech Ceiling Mount Sensor, Switching, 2-zone, 2,000SF, 120-277VAC	AC220-DMW
Wireless Companion Switch, Battery Powered, White	SBK00-CSW
Wireless Companion Dimmer, Battery Powered, White	SBK00-CDW
Wireless Companion Keypad, 4-Button (ON, OFF, Raise, Lower), Battery Powered, White	SBK00-4DW
Wireless Companion Keypad, 4-Button (MAX, MID, LOW, OFF), Battery Powered, White	SBK00-4PW
Glass Mounting Kit for Wireless Companion Devices	WPN01-00W
Low Voltage Keypad, 1-button	PLVSW-1LW
Low Voltage Keypad, 2-button	PLVSW-2LW
Low Voltage Keypad, 4-button	PLVSW-4LW

Smart IP66 PIR Integrated Fixture Mount Sensor	
Description	Cat. No.
Smart PIR 0-10V Dimming Sensor, End/Fixture Mount, 120-277VAC	OFD1Z-ISW
Smart PIR 0-10V Dimming Sensor, End/Fixture Mount, Universal 120-480VAC	OFDUZ-ISW

Verifeye® Submetering Solutions

Please visit **leviton.com/verifeye** to find complete ordering information for Verifeye® Submetering Solutions, or contact your Leviton representative

Marine Power

Please visit leviton.com/markets/marine for complete ordering information, or contact your Leviton representative.

Medical Grade Power Strips

TYPE 3 — Surge Medical Grade Power Strips					
Stock Configurations	Current Rating	AC Power Cord Length	2 Outlet	4 Outlet	6 Outlet
Surge Protective Medical Grade Power Strips	15A (12 A max continuous load)	7 Feet	5302M-1S7	5304M-1S7	5306M-1S7
		15 Feet	5302M-1S5	5304M-1S5	5306M-1S5
	20A (16 A max continuous load)	7 Feet	5302M-2S7	5304M-2S7	5306M-2S7
		15 Feet	5302M-2S5	5304M-2S5	5306M-2S5
Surge Protective Medical Grade Power Stripswith Load Monitoring Inform™ Technology	15A (12 A max continuous load)	7 Feet	—	53C4M-1S7	53C6M-1S7
		15 Feet	—	53C4M-1S5	53C6M-1S5
	20A (16 A max continuous load)	7 Feet	—	53C4M-2S7	53C6M-2S7
		15 Feet	—	53C4M-2S5	53C6M-2S5



Looking for More?

Get the Latest Full-Line Catalog (L-400)

Get all of the up-to-date Leviton product information, downloaded to your mobile device. With nearly 700 pages of valuable information in a neatly organized, searchable and easy to navigate format, the electronic Full-Line Catalog is updated seasonally to provide the latest offerings as soon as they're released. **Scan or visit leviton.com/catalog for access to the latest version.**

EXPLORE ALL
PRODUCTS IN OUR
L-400 CATALOG



Leviton Manufacturing Co., Inc.

201 N Service Rd, Melville, NY 11747

Phone: 1-800-323-8920

Tech Line: 1-800-824-3005 (8:30 AM-7:30 PM E.S.T. Monday-Friday)

We build what's next to light, power, and connect everyday spaces.

Specifications subject to change without notice.

© 2026 Leviton Manufacturing Co., Inc. All Rights Reserved.

Visit **leviton.com** for complete product and ordering information.

THE FUTURE IS ON®

ED-B-00450 | Q2 2026