

High-Capacity 8" Versi-Duct[®] Cable Management System

APPLICATION

A vertical cable management system designed to optimize performance and protect network cabling infrastructure. This high-capacity system provides a simplified solution for the routing of copper and fiber cables and mounts onto any industry standard equipment rack. The 8" wide channel was built to maximize cable handling capacity while protecting cable integrity in an injected molded product. This vertical management system comes with cable concealing covers and is kitted with accessories to properly manage the installation.



SPECIFICATION

A vertical cable management system designed for copper and fiber cabling systems. The management system shall be cULus listed, PVC rated 94V-0, ABS rated UL 94HB, and compliant with ANSI/TIA 568 standards. Mounting hardware shall be included to insure the proper installation to infrastructure. Vertical Management System shall mount onto standard equipment racks. The management system shall offer an assortment of accessories, including a bend radius slack loop organizer and cable retainers.

ACCESSORIES

- **Slack Loop Organizer** – Stores cable slack and maintains proper bend radius for CAT 6A applications. Designed to fit in the center of the channel, it can be mounted in six locations according to the needs of the installation.
- **Cable Retainer** – Mounts on the channel fingers and snaps into multiple positions along the fingers to secure cable bundles.
- **Mounting Brackets** – Additional brackets may be used to center mount channel between two racks.

FEATURES

- Versatile solution for fiber and copper cable organization and management
- Durable ABS plastic channels withstand years of use in demanding environments
- Large finger passthrough space aligns with rack units
- Radius edges protect cable routing
- Front only and front/rear configurations
- Dual hinged, cable concealing covers included
- Channels kitted with cable retainers, slack loop organizers, mounting brackets, and covers
- Accommodates top, bottom, side and pass-through cable routing
- Mount on standard equipment racks

DESIGN CONSIDERATIONS

- Product is comprised of two 40" long sections that span the full length of a standard equipment rack
- Includes mounting brackets intended to secure channel to side of industry standard equipment rack
- Additional mounting brackets may be added for center mounting options between two racks
- Slack loop organizer accommodates 60 lbs of cable

STANDARDS & REGULATIONS

- cULus Listed
- ANSI/TIA 568

MECHANICAL SPECIFICATIONS

Dimensions:	See second page
Materials (channel):	ABS rated UL 94HB
Materials (cover):	PVC rated UL 94V-0


WARRANTY INFORMATION

For Leviton product warranties, go to leviton.com/ns/warranty

8980L-xxx, 89265-xxx

PRODUCT SPECIFICATIONS

8980L-xxx, 89265-xxx

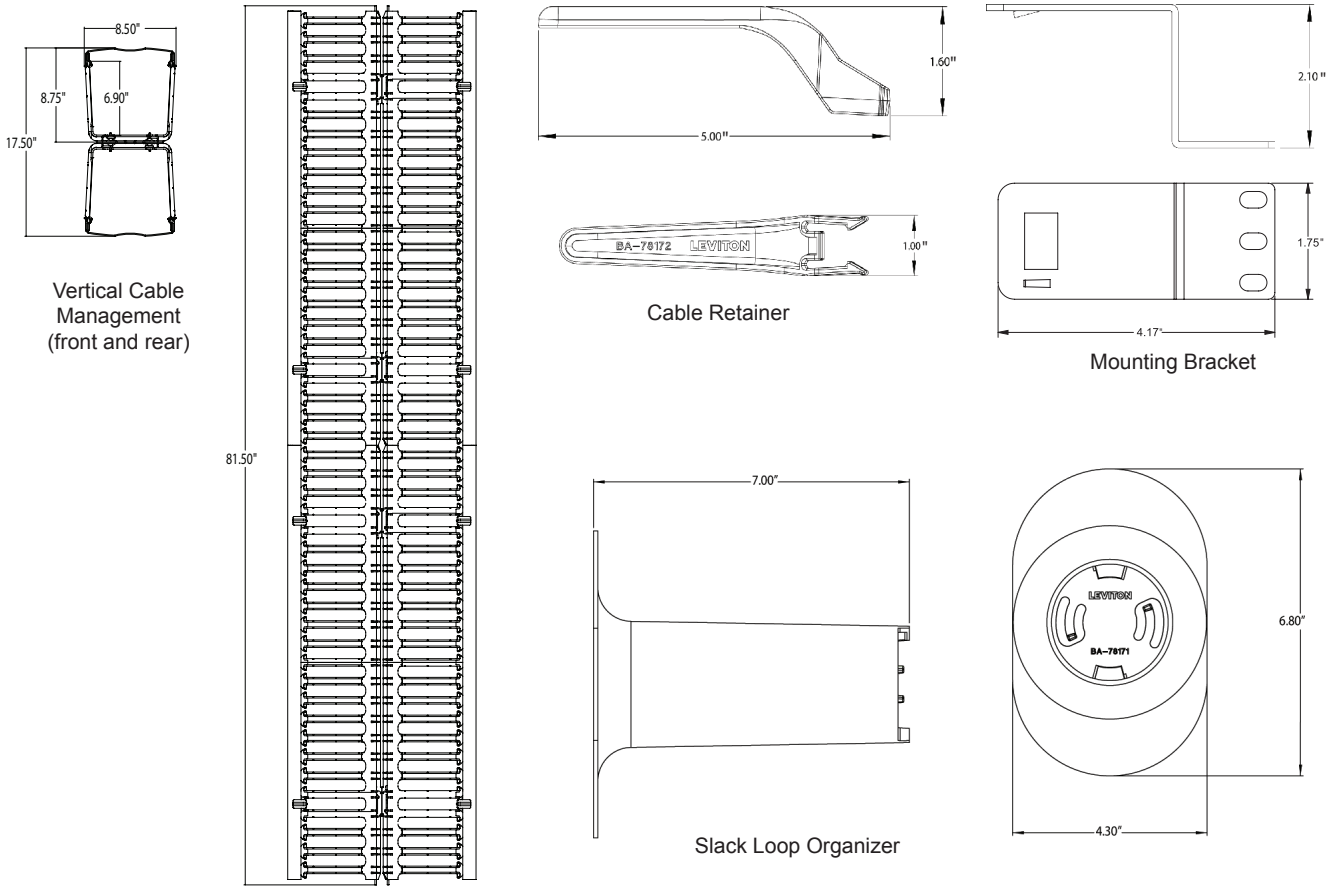

8980L-xxx, 89265-xxx

Feature	Channel Depth (WxD)	Area (In ²)	Cat 6A Capacity (.354" Cable)	Cat 6 Capacity (.250" Cable)	Cat 5e Capacity (.180" Cable)
8" channel size (per side)	8"x 8"	60	192	384	738
Finger Spacing	5.5" x 1"	5.5	24	60	114
Large Passthrough	4.8" x 2.6"	12.7	72	120	258
Small Passthrough	2.6" x 2.6"	6.8	36	72	138

VERSI-DUCT® 8" CHANNEL VERTICAL CABLE MANAGEMENT & ACCESSORIES

Description	Front Only	Front & Rear
Vertical 80" Length, 8" W x 8" D channel, standard black cover, hinged	8980L-VFO	8980L-VFR
Vertical 40" Cover, 8" W, black (set of 4)	—	8980L-SRC
Vertical Center Mounting Bracket, 8" channel (bag of 4)	—	89265-BKT
Vertical Cable Retainer, 8" channel (bag of 6)	—	89265-WR1
Vertical Slack Loop Organizer, 8" channel (package of 2)	—	89265-SL1

For further support information, visit leviton.com/ns/support