


## BNC Feedthrough QuickPort® Connectors

### APPLICATION

BNC Feedthrough QuickPort Connectors feature nickel- or gold-plated female-to-female connectors with twist-on front and rear connections. The feedthrough design is ideal for high-end video and CCTV applications.

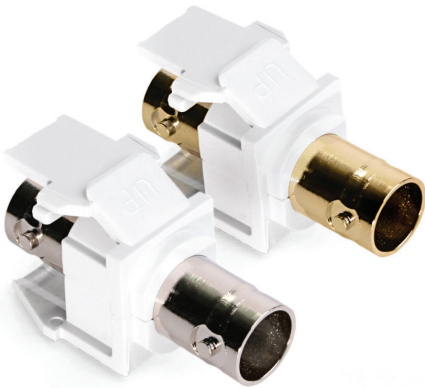

### SPECIFICATION

Modules for coaxial cable shall be individual snap-in style female-to-female feedthrough connectors, and shall fit all other installed Leviton telecommunications wallplates, outlets, and field-configurable patch panels and patch blocks. The connectors shall be available in six colors (ivory, white, light almond, grey, black, and brown) to match the housings or provide unique color coding for port ID. The modules shall be UL listed. All plastics used in construction of the module bodies shall be fire retardant.

### FEATURES

- Compatible with all QuickPort housings and wallplates
- Female-female BNC feedthrough connector
- Available in nickel- and gold-plated finishes
- 50 ohm impedance

### DESIGN CONSIDERATIONS

- BNC Feedthrough QuickPort Connectors snap into any housing with the QuickPort name: flush- and surface-mount outlets, Multimedia Outlet System (with adapter), patch panels, and patch blocks
- Check clearance behind proposed location of BNC connector, to ensure space for proper bend-radius
- Available in six colors (ivory, white, light almond, grey, black, and brown) to match the housings or provide unique color coding for port ID
- BNC connectors are for cables that have male connectors already installed on cables

### STANDARDS COMPLIANCE

- cULus Listed (UL 1863, CAN/CSA-C22.2 No. 182.4-1990)

### PHYSICAL SPECIFICATIONS

Dimensions: See page two  
Materials: Snap-in module bodies are high-impact, fire-retardant plastic  
Impedance: 50 Ohms

### COUNTRY OF ORIGIN

China


### WARRANTY INFORMATION

For a copy of Leviton product warranties, visit [www.leviton.com/warranty](http://www.leviton.com/warranty).

41084-BxF, 40832-0Bx

**ELECTRONIC FILES**

For CAD files, typical specs, or technical drawings (.DXF, .DWG), visit [www.leviton.com](http://www.leviton.com).

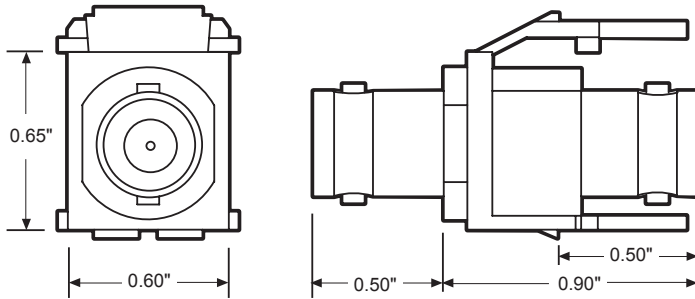

**41084-BxF, 40832-0Bx**

**PART NUMBERS**

Description	IVORY	WHITE	LT. ALMOND	GREY	BLACK	BROWN
BNC Feedthrough QuickPort® Connector, nickel plated	41084-BIF	41084-BWF	41084-BTF	41084-BGF	41084-BEF	41084-BBF
BNC Feedthrough QuickPort Connector, gold plated	40832-0BI	40832-0BW	40832-0BT	—	—	—



**Leviton Network Solutions**  
 2222 - 222nd St. SE  
 Bothell, WA 98021-4416

**Asia / Pacific**  
 T +1.631.812.6228  
 E [infoasean@leviton.com](mailto:infoasean@leviton.com)

**Canada**  
 T +1.514.954.1840  
 E [pcservice@leviton.com](mailto:pcservice@leviton.com)

**Caribbean**  
 T +1.954.593.1896  
 E [infocaribbean@leviton.com](mailto:infocaribbean@leviton.com)

**China**  
 T +852.2774.9876  
 E [infochina@leviton.com](mailto:infochina@leviton.com)

**Colombia**  
 T +57.1.743.6045  
 E [infocolombia@leviton.com](mailto:infocolombia@leviton.com)

tel 1-800-824-3005  
 tel +1-425-486-2222  
[appeng@leviton.com](mailto:appeng@leviton.com)  
[www.leviton.com](http://www.leviton.com)

**Europe**  
 T +33.6.8869.1380  
 E [infoeurope@leviton.com](mailto:infoeurope@leviton.com)

**India / SAARC**  
 T +91.80.4322.5678  
 E [infoindia@leviton.com](mailto:infoindia@leviton.com)

**Mexico**  
 T +52.55.5082.1040  
 E [lsamarketing@leviton.com](mailto:lsamarketing@leviton.com)

**Middle East & Africa**  
 T +971.4.886.4722  
 E [lmeinfo@leviton.com](mailto:lmeinfo@leviton.com)

**South Korea**  
 T +82.2.3273.9963  
 E [infokorea@leviton.com](mailto:infokorea@leviton.com)