


# Lev-Lok® Decora® Tamper-Resistant Receptacle with Two USB Ports

15 and 20 Amp, 125 Volt • Type A/A and Type A/C USB Ports  
Commercial Specification Grade and Heavy-Duty Hospital Grade

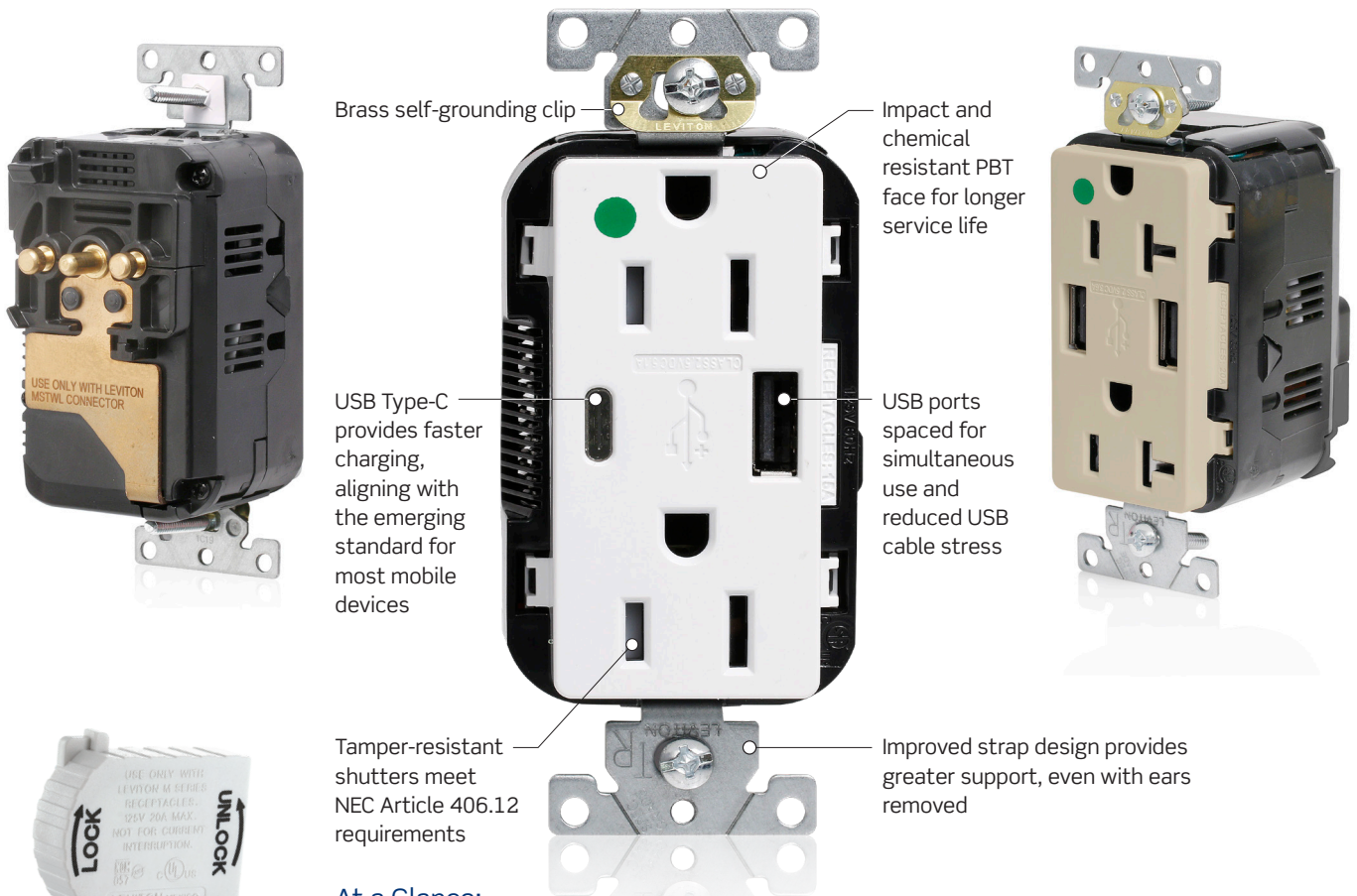

- At a Glance:**
- Type A/A USB Ports have a combined total of 3.6A of charging power
  - Type A/C USB Ports have a combined total of 5.1A charging power
  - Common applications include health care facilities, lobbies & waiting rooms, airports, hospitality, and educational institutions

- Type-A USB**
- The most recognizable and commonly sought USB port
  - Used with desktops, laptops, tablets, video game consoles, smart TVs, and more

- Type-C USB**
- The emerging standard for charging and transferring data
  - Used with the newest laptops, phones, and tablets including the latest Apple MacBook and the Chromebook Pixel from Google

A mating MSTWL Lev-Lok Wiring Device Module is required for use, sold separately.

## Specifications

Catalog Numbers	M56AA/M56AC	M58AA/M58AC
<b>AC Horsepower Ratings</b>		
At Rated Voltage	1/2 hp	1 hp
<b>Electrical Specifications</b>		
Amperage	15 A	20 A
Voltage	125 VAC	
Grounding	Self-Grounding	
Pole	2	
Wire	3	
Dielectric Voltage	Withstands 2000V per CSA	
Temperature Rise	Max 30°C after 100 cycles OL	
Interrupting Rating	Certified for full-rated current and voltage	
<b>Environmental Specifications</b>		
Flammability	Rated V-0 per UL 94	
Operating Temp.	-10°C to 40°C	
<b>Material Specifications</b>		
Face Material	Thermoplastic	
Body Material	PBT Thermoplastic polyester resin	
Mounting Strap	Galvanized Steel	
Ground Clip	Brass	
Ground Contacts	Brass	
Mounting Screws	#6 Plated Steel	
Locking Pin	Solid Brass	
Shutter Material	Thermoplastic	
Shutter Mechanism	Acetal	
<b>Mechanical Specifications</b>		
Product ID	Ratings are marked on device	
Termination	Modular	
Strap Construction	Through-Strap	
<b>Product Features</b>		
Device Type	Lev-lok® Decora® Duplex Receptacle	
Feature	Tamper-Resistant, with USB, Smooth Face	
Grade	Commercial Specification or Heavy-Duty Hospital Grade	
NEMA Config.	5-15R	5-20R
Total Charging Power	18 W, 3.6 A total or 25 W, 5.1 A total	
Single Port Charging Power	12 W or 15 W	
USB Cable Compat.	Type A or Type C	
<b>Standards and Certifications</b>		
NEMA	WD-1 & WD-6	
ANSI	C-73	
Certification/Listing	cCSAus, NOM-ANCE	
Applicable Standards	UL 498 and 1310, CSA C22.2 Nos. 42 and 223	
<b>Warranty</b>		
Warranty	5-Year Limited	

## Ordering Information

Description	Rating	Default Catalog Numbers
Lev-Lok® Commercial Specification Grade TR Receptacle with USB Type A/A	15 A	M56AA-x
	20 A	M58AA-x
Lev-Lok Hospital Grade TR Receptacle with USB Type A/A	15 A	M56AA-HGx
	20 A	M58AA-HGx
Lev-Lok Commercial Specification Grade TR Receptacle with USB Type A/C	15 A	M56AC-x
	20 A	M58AC-x
Lev-Lok Hospital Grade TR Receptacle with USB Type A/C	15 A	M56AC-HGx
	20 A	M58AC-HGx

## Color Legend

Brown	Ivory	White	Black	Blue
base #	I	W	E	B
Gray	Red	Lt. Almond	Green	Orange
GY or G	R	T	N	O


Base color is Brown, for other colors add the appropriate color indicator to the base catalog number - Ex: M58AC-HG**W**

(NOTE: Blue, Green and Orange not available for Hospital Grade Receptacles)



Mating MSTWL Lev-Lok Wiring Device Module required for use, sold separately

## Dimensions

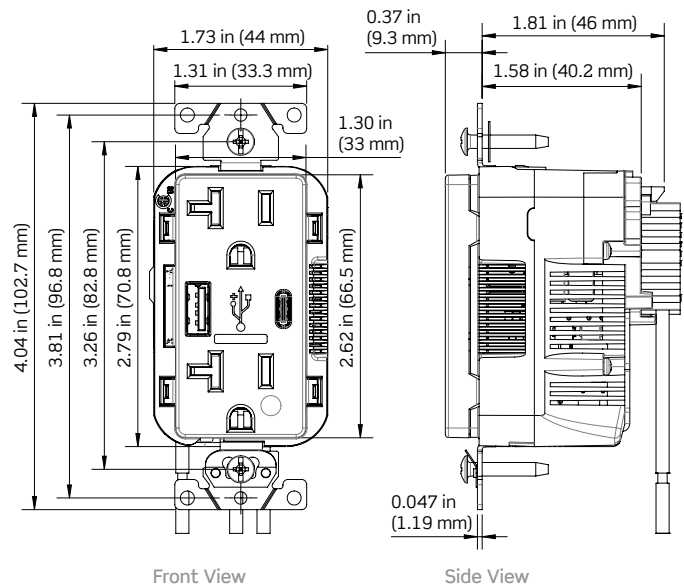

Visit our Website at:

[www.leviton.com/levlok](http://www.leviton.com/levlok)

email: [commercial@leviton.com](mailto:commercial@leviton.com)

Q-1181

080619

Leviton Manufacturing Co., Inc.

201 N Service Rd, Melville, NY 11747

Telephone: 1-800-323-8920 • FAX: 1-800-832-9538

Tech Line (8:30AM-7:30PM E.S.T. Monday-Friday): 1-800-824-3005

© 2019 Leviton Manufacturing Co., Inc. All rights reserved.

