


Single Receptacles

Heavy-Duty Industrial Specification Grade
Weather-Resistant

15 A & 20 A, 125 V & 250 V

These single receptacles provide compliance for Article 406.9 of the National Electrical Code (NEC) in wet and damp locations and include added protection against corrosion, UV degradation and cold impact damage.

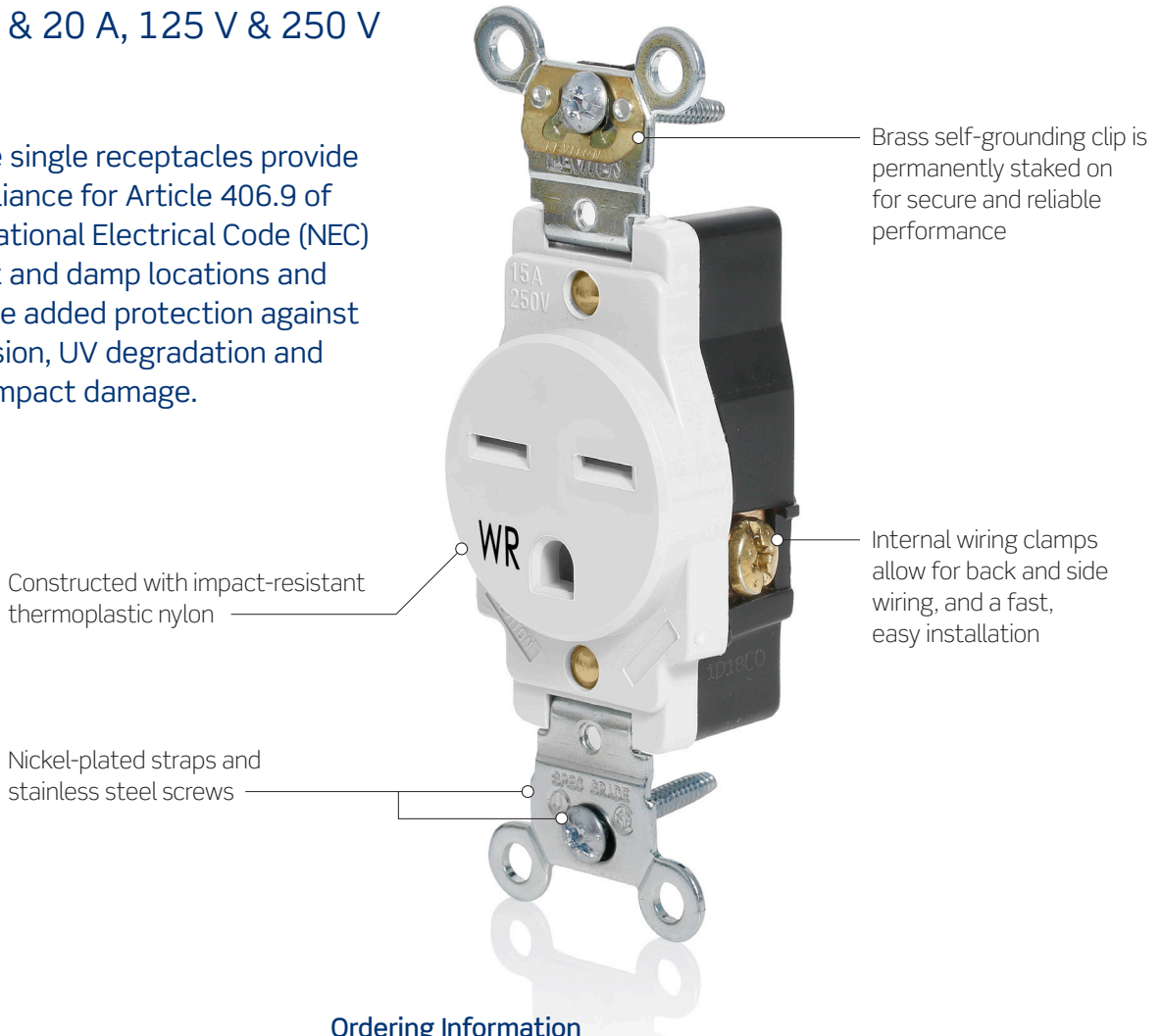

Ordering Information


Ratings		15 A/125 V	20 A/125 V	15 A/250 V	20 A/250 V
NEMA Config		5-15R	5-20R	6-15R	6-20R
Order ID	Brown	W5261	W5361	W5661	W5461
	Ivory	W5261-I	W5361-I	W5661-I	W5461-I
	Gray	W5261-GY	W5361-GY	W5661-GY	W5461-GY
	White	W5261-W	W5361-W	W5661-W	W5461-W
	Light Almond	W5261-T	W5361-T	W5661-T	W5461-T
	Red	W5261-R	W5361-R	N/A	N/A
	Black	W5261-E	W5361-E	W5661-E	W5461-E
	Yellow	W5261-Y	W5361-Y	W5661-Y	W5461-Y

Specifications


Order ID	W5261	W5361	W5661	W5461
Electrical Specifications				
Horsepower Rating	½ hp	1 hp	1-½ hp	2 hp
Amperage	15 A	20 A	15 A	20 A
Voltage	125 V	125 V	250 V	250 V
Grounding	Self-Grounding			
Pole(s)	2			
Wire(s)	3			
Dielectric Voltage	2000 VAC			
Temperature Rise	Max 30°C			
Interrupting Rating	Certified for full-rated current and voltage			
Environmental Specifications				
Flammability Rating	V-2			
Operating Temperature	Maximum Continuous 75°C, Minimum -40°C (w/o impact)			
Material Specifications				
Face	Nylon			
Body	Nylon			
Mounting Strap	Nickel-Plated Steel			
Line Contacts	Brass Triple Wipe 0.031"			
Self-Grounding Clip	Brass			
Grounding Screw	#8 Brass			
Ground Contacts	Brass			
Mounting Screws	#6 Stainless Steel			
Terminal Clamps	Brass			
Terminal Screws	#10 Brass			
Mechanical Specifications				
Product ID	Ratings are marked on device			
Wire Accomodation	#14-#10 AWG Solid or Stranded			
Termination	Back and Side Wire			
Strap Construction	Wraparound Strap			
Product Features				
Feature(s)	Weather-Resistant, Smooth Face, RoHS Compliant			
Device Type	Single Receptacle Outlet			
Grade	Heavy-Duty Industrial Specification Grade			
NEMA Configuration	5-15R	5-20R	6-15R	6-20R
Standards & Certifications				
NEMA	WD-1 and WD-6			
Applicable Standards & Certifications	UL 498; CSA C22.2, No. 42; Fed Spec WC-596; NOM			
Warranty				
Warranty	10-Year Limited			

Dimensions

Front View

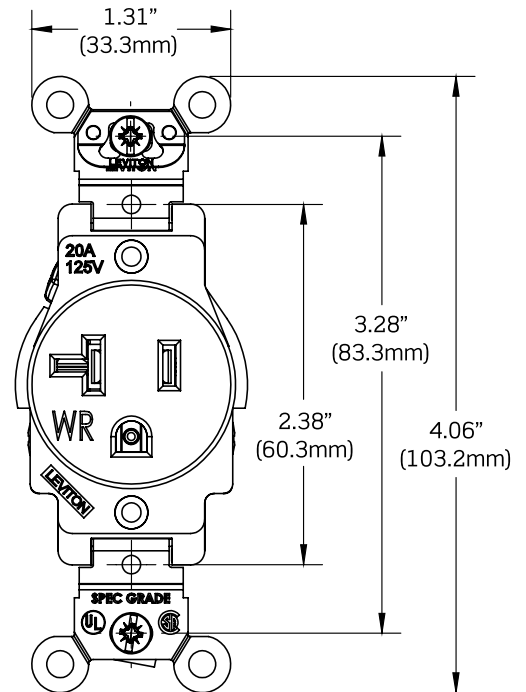

Side View

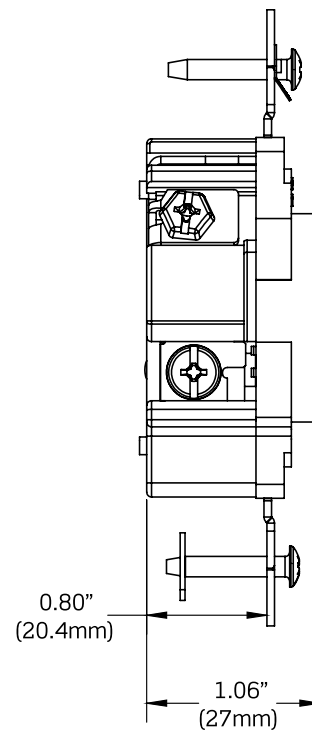

Visit our Website at:
www.leviton.com/commercial
 email: commercial@leviton.com

Q-1152

112118

Leviton Manufacturing Co., Inc.
 201 N Service Rd, Melville, NY 11747
 Telephone: 1-800-323-8920 • FAX: 1-800-832-9538
 Tech Line (8:30AM-7:30PM E.S.T. Monday-Friday): 1-800-824-3005

© 2018 Leviton Manufacturing Co., Inc. All rights reserved.

