

ORDER FORM

Dockhead DH2 Large Power Outlet Box

10" X 12" POWER OUTLET BOX FOR MARINE:

- Preassembled with distribution block, wiring devices with weather-resistant covers, and front and bottom LED lights
- Allows up to 4 wiring devices (see locations A, B, C, D per diagram on next page)
- Can be ordered with or without stand

CONSTRUCTION:

- Polycarbonate housing

STANDARDS:

- NEMA 3R, UL-231, CSA 22.2 No. 29, NFPA 303, NFPA 70

WARRANTY:

- Housing: 5 years
- Wiring Devices: 1 year



DATE:

JOB NAME:

DISTRIBUTOR NAME & ACCOUNT NUMBER:

CITY:

STATE:

ZIP:

PO NUMBER:

CONTACT NAME:

EMAIL:

PHONE:

LEVITON SALES PERSON:



Visit our Website at:

www.leviton.com/powerpedestals

email: industrial@leviton.com

Q-1491A

052623

Leviton Manufacturing Co., Inc.

201 N Service Rd, Melville, NY 11747

Telephone: 1-800-323-8920 • FAX: 1-800-832-9538

Tech Line: 1-800-824-3005 (M-F 8AM-10PM; Sat 9AM-7PM; Sun 9AM-5PM)

© 2023 Leviton Manufacturing Co., Inc. All rights reserved.

ORDERING NUMBER:

Ordering example: DH2-20S-20S-30S-20S-W-A-SD-W0-DE1-SE1



DH2 - - - - -
 1 2 3 4 5 6 7 8 9 10 11 12

1 MODEL	2 RECEPTACLE/BREAKER Device Location A	3 RECEPTACLE/BREAKER Device Location B	4 RECEPTACLE/BREAKER Device Location C
DH2 Dockhead 10" x 12" Base Unit Includes Box and LED Clear or Amber with Front and Bottom Lens	R0 No Receptacle 20S 20A GFI Recept. w/Std. Brkr. 30S 30A (125V) Recept. w/Std. Brkr. 30E 30A (125V) Recept. w/30mA EPD Brkr. 50S 50A (125V) Recept. w/Std. Brkr. 50E 50A (125V) Recept. w/30mA EPD Brkr. (Uses 2-Pole 50A EPD Brkr./1-Pole 50A EPD Brkr. Unavail.) 50S2 50A (125/250V) Recept. w/Std. Brkr. 50E2 50A (125/250V) Recept. w/30mA EPD Brkr. CO Cable Only Recept. Cvr. - 1 Conn. (Only Avail. in White) C5 CAT5 Internet Conn.	R0 No Receptacle 20S 20A GFI Recept. w/Std. Brkr. 30S 30A (125V) Recept. w/Std. Brkr. 30E 30A (125V) Recept. w/30mA EPD Brkr. 50S 50A (125V) Recept. w/Std. Brkr. 50E 50A (125V) Recept. w/30mA EPD Brkr. (Uses 2-Pole 50A EPD Brkr./1-Pole 50A EPD Brkr. Unavail.) 50S2 50A (125/250V) Recept. w/Std. Brkr. 50E2 50A (125/250V) Recept. w/30mA EPD Brkr. CO Cable Only Recept. Cvr. - 1 Conn. (Only Avail. in White) C5 CAT5 Internet Conn.	R0 No Receptacle 20S 20A GFI Recept. w/Std. Brkr. 30S 30A (125V) Recept. w/Std. Brkr. 30E 30A (125V) Recept. w/30mA EPD Brkr. 50S 50A (125V) Recept. w/Std. Brkr. 50E 50A (125V) Recept. w/30mA EPD Brkr. (Uses 2-Pole 50A EPD Brkr./1-Pole 50A EPD Brkr. Unavail.) 50S2 50A (125/250V) Recept. w/Std. Brkr. 50E2 50A (125/250V) Recept. w/30mA EPD Brkr. CO Cable Only Recept. Cvr. - 1 Conn. (Only Avail. in White) C5 CAT5 Internet Conn.


5 RECEPTACLE/BREAKER Device Location D	6 RECEPTACLE COVER COLOR	8 BUS BAR	10 WATER HOOKUP TYPE*
R0 No Receptacle 20S 20A GFI Recept. w/Std. Brkr. 30S 30A (125V) Recept. w/Std. Brkr. 30E 30A (125V) Recept. w/30mA EPD Brkr. 50S 50A (125V) Recept. w/Std. Brkr. 50E 50A (125V) Recept. w/30mA EPD Brkr. (Uses 2-Pole 50A EPD Brkr./1-Pole 50A EPD Brkr. Unavail.) 50S2 50A (125/250V) Recept. w/Std. Brkr. 50E2 50A (125/250V) Recept. w/30mA EPD Brkr. CO Cable Only Recept. Cvr - 1 Conn. (Only Available in White) C5 CAT5 Internet Conn.	WH White B Blue GR Green T Tan GY Gray Y Yellow	SD Straight Distrib. Block SPD Single Phase Loop Distrib. Block SPS Single Phase Loop Studded Distrib. Block T30 Three Phase Loop 300MCM Distrib. Block T50 Three Phase Loop 350MCM Distrib. Block SMS Split Mini Straight Distrib. Blocks	W0 No Water W11 3/4" 1/4 Turn Water Valve - QTY 1 W21 3/4" Water Valve w/Backflow Preventer - QTY 1 W31 1/2" 1/4 Turn Water Valve - QTY 1 W41 1/2" Water Valve w/Backflow Preventer - QTY 1 W12 3/4" 1/4 Turn Water Valve - QTY 2 W22 3/4" Water Valve w/Backflow Preventer - QTY 2 W32 1/2" 1/4 Turn Water Valve - QTY 2 W42 1/2" Water Valve w/Backflow Preventer - QTY 2

11 KILOWATT HOUR METERS Meter Location 1	12 KILOWATT HOUR METERS Meter Location 2
M0 NONE SE1 Single Element Meter - QTY 1 DE1 Dual Element Meter - QTY 1 SE2 Single Element Meter - QTY 2 DE2 Dual Element Meter - QTY 2 SE3 Single Element Meter - QTY 3 DE3 Dual Element Meter - QTY 3	M0 NONE SE1 Single Element Meter - QTY 1 DE1 Dual Element Meter - QTY 1 SE2 Single Element Meter - QTY 2 DE2 Dual Element Meter - QTY 2 SE3 Single Element Meter - QTY 3 DE3 Dual Element Meter - QTY 3

NOTE: * Water Hookup Types can only be selected if Stand (ST2) is selected. If No Stand (ST0) is selected, Water Hookup Type should default to "W0" No Water.

QUANTITY:

NOTES:

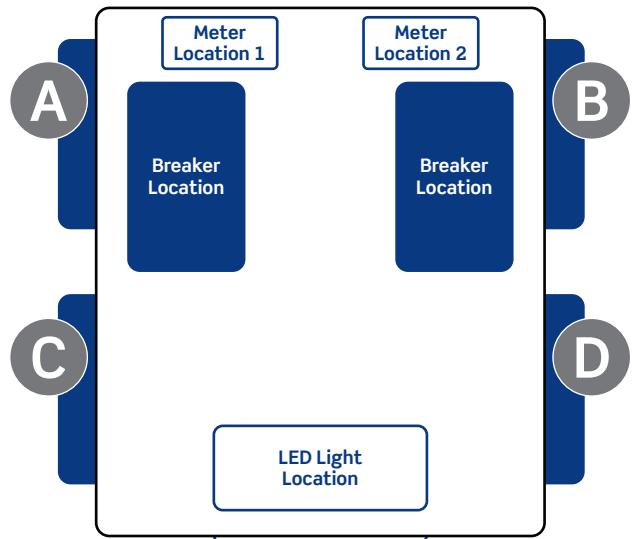

CUSTOMER SIGNATURE  (Indicates build approval)

With this signature the customer acknowledges being advised that these Made-To-Order pedestals are non-cancelable, non-refundable, and non-returnable.